

Accessories Magnetic sensors

magnet rotor				magnet rotor (zero pulse)			
part nr. see chart				part nr. see chart			
dimension without zero pulse				dimension with zero pulse			
	32 poles	36 poles	64 poles		32 poles	36 poles	64 poles
A	30,5	30,5	56	A	40	40	66
B	20	20	35	B	20	20	66
C	6H7	6H7	25E7	C	6H7	6H7	25E7
D	14	14	15	D	17	17	18
E	7 / 5	7 / 5	8 / 6	E	8 / 5	8 / 5	9 / 9
F	M3	M3	M4	F	M3	M3	M4
G	-	-	-	G	30,5	30,5	56
H	-	-	-	H	18	18	31,3
material	alu	alu	alu	material	alu	alu	alu
part number	134061	157948	143924	part number	132124	147433	150984

mounting bracket MDFK 08	
part number	134683
mounting MDFK 08 (0-pulse)	

ring magnet	32 poles
part number	156640

 
 
 
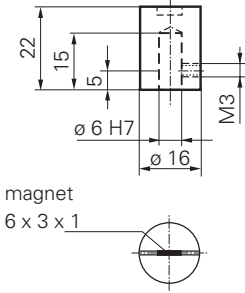

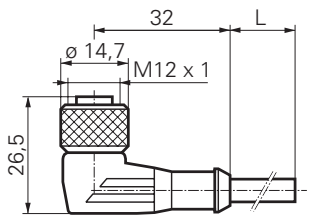
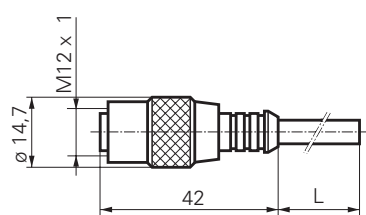
 
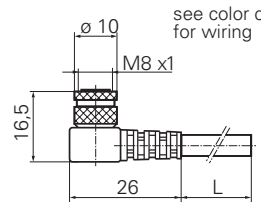
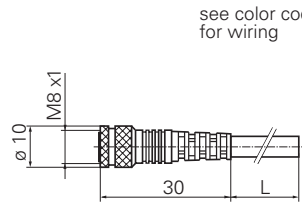
ring magnet	36 poles
part number	147431

ring magnet	64 poles
part number	143920

Ring magnet can be designed to meet application specific requirements.

Accessories

Magnetic sensors

magnetic strip for MLFK		magnetic strip for MLFK		self-adhesive protective tape											
length	part number	length	part number	part number	157164										
50 mm	128662	L= (cut to length)	147044												
150 mm	128663														
300 mm	128664														
L= (cut to length)	128606														
 <p>pole width 2 mm strip thickness 1,4 mm</p>		 <p>pole width 1 mm strip thickness 1,4 mm</p>		 <p>strip thickness 0,25 mm</p>											
rotor															
part number	123344														
 <p>magnet 6 x 3 x 1</p>															
connector ESW 33A		connector ESG 34A		pin-assignment con. 4-pin (M12)											
part number	cable length	part number	cable length												
ESW 33AH0200	4-pin 2 m PUR	ESG 34AH0200	4-pin 2 m PUR	<table border="1"> <thead> <tr> <th>pin nr.</th> <th>color</th> </tr> </thead> <tbody> <tr> <td>1</td> <td>BN (brown)</td> </tr> <tr> <td>2</td> <td>WH (white)</td> </tr> <tr> <td>3</td> <td>BU (blue)</td> </tr> <tr> <td>4</td> <td>BK (black)</td> </tr> </tbody> </table>		pin nr.	color	1	BN (brown)	2	WH (white)	3	BU (blue)	4	BK (black)
pin nr.	color														
1	BN (brown)														
2	WH (white)														
3	BU (blue)														
4	BK (black)														
ESW 33AH0500	4-pin 5 m PUR	ESG 34AH0500	4-pin 5 m PUR												
ESW 33AH1000	4-pin 10 m PUR	ESG 34AH1000	4-pin 10 m PUR												
halogen-free		halogen-free													
															
connector ESW 31A		connector ESG 32A		pin-assignment con. 4-pin (M8)											
part number	cable length	part number	cable length												
ESW 31AH0200	4-pin 2 m PUR	ESG 32AH0200	4-pin 2 m PUR	<table border="1"> <thead> <tr> <th>pin nr.</th> <th>color</th> </tr> </thead> <tbody> <tr> <td>1</td> <td>BN (brown)</td> </tr> <tr> <td>2</td> <td>WH (white)</td> </tr> <tr> <td>3</td> <td>BU (blue)</td> </tr> <tr> <td>4</td> <td>BK (black)</td> </tr> </tbody> </table>		pin nr.	color	1	BN (brown)	2	WH (white)	3	BU (blue)	4	BK (black)
pin nr.	color														
1	BN (brown)														
2	WH (white)														
3	BU (blue)														
4	BK (black)														
ESW 31AH0500	4-pin 5 m PUR	ESG 32AH0500	4-pin 5 m PUR												
ESW 31AH1000	4-pin 10 m PUR	ESG 32AH1000	4-pin 10 m PUR												
halogen-free		halogen-free													
 <p>see color code for wiring</p>		 <p>see color code for wiring</p>													